

Description	Dimensions (W x H mm)	Cat Ref.
IP66 Wall Switches		
10AX 1 Gang 2 Way Switch	90 x 90	WXPPS12
10AX 2 Gang 2 Way Switch	90 x 90	WXPPS22
20AX Double Pole 1 Gang 1 Way Switch	90 x 90	WXDP84
10A1 Gang Bell Push Switch	90 x 90	WXPPS12B
IP66 Socket Outlets		
13A 1 Gang Double Pole Unswitched Socket	103 x 116.5	WXPS81
13A 1 Gang Double Pole Switched Socket	103 x 116.5	WXPS81
13A 2 Gang Double Pole Unswitched Socket	164 x 116.5	WXPS82
13A 2 Gang Double Pole Switched Socket	164 x 116.5	WXPS82
IP66 Fused Connection Units		
13A Double Pole Fused Connect Unit with Flex Outlet	103 x 116.5	WXPSU83FO



Hager Ltd.

Hortonwood 50
Telford
Shropshire
TF1 7FT

Customer Contact Centre: 01952 675612
Technical Helpline: 01952 675689

[hager.com/uk](https://www.hager.com/uk)

sales@hager.co.uk

technical@hager.co.uk



WhatsApp Tech Support: 07778 161000



@HagerUK



@HagerUK



Hager UK



@HagerukTV



@Hager_uk

At A Glance

Sollysta IP66



**Our IP66 range
is robust and
durable solution
for indoor
or outdoor
applications.**



Protection

Manufactured from a tough, durable thermoplastic, the IP66 range is ideal for applications where wiring accessories may be vulnerable to the potentially harmful effects of dust and water ingress. The ip66 rating assures total protection.




Moulded Plugs

Extended enclosure for extra wide gel seal mean even moulded on plugs can be accommodated.



Secure

A padlock of up to 5mm diameter shank can be fitted to the enclosure to prevent unauthorised use.

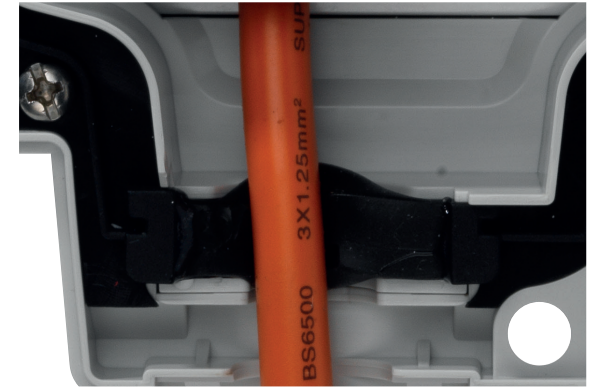

Soft Sealing

The factory fitted soft gel seal fits snugly around power cables to maintain the IP66 rating in use with the lid fully closed.



180 Degrees

A unique dual action hinge allowing the lip to be opened a full 180 degrees for ease of plug insertion and switch operation.